




レベル検知用静電容量センサ BCS

角型, , 16×34×8 mm Micro-Box - SMARTLEVEL 50

- 配線を用いてテーチング可能
- IO-Linkタイプも用意
- 結束バンドでチューブへ簡単取付け



プラスチックまたはガラス製パイプ内の導電性媒体を検出
最大10mmの容器の壁面を通して導電性媒体を検出
酸や塩基など、最大50mS/cmの高い導電性媒体を検知
医療技術：体液の検出(泡だった血液など)
半導体産業：プロセス用の薬液などを非接触検出

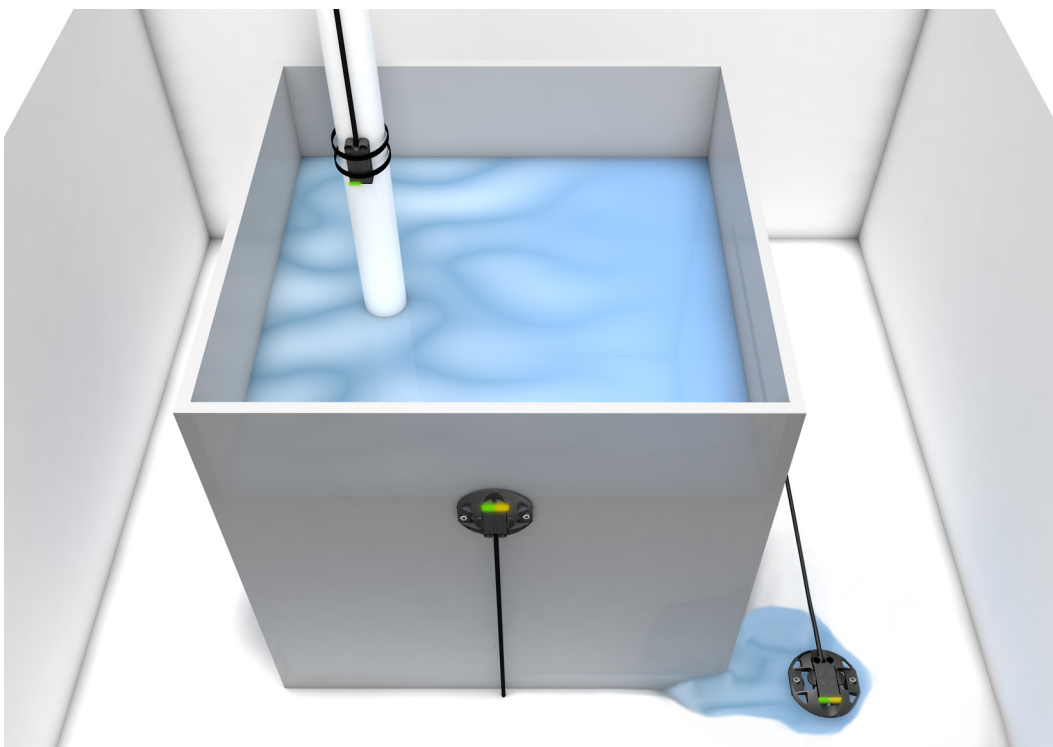



寸法		16.0x8.0x34.0 mm	16.0x8.0x34.0 mm	16.0x8.0x34.0 mm
製品範囲		Capacitive Sensors	Capacitive Sensors	
機械的な取付け条件		容器外壁で面一	容器外壁で面一	容器外壁で面一
PNP, 常時閉 (NC)	注文コード	BCS0130	BCS012J	
	銘板	BCS R08RRE-POMFHC-EP00,3-GS75	BCS R08RRE-POMFHC-EP02	
PNP, 常時開 (NO)	注文コード	BCS012Z	BCS012H	
	銘板	BCS R08RRE-PSMFHC-EP00,3-GS75	BCS R08RRE-PSMFHC-EP02	
PNP, NO/NC, IO-Link	注文コード			BCS012P
	銘板			BCS R08RRE-PIMFHC-EP00,3-GS04
NPN, 常時閉 (NC)	注文コード	BCS0132	BCS012L	
	銘板	BCS R08RRE-NOMFHC-EP00,3-GS75	BCS R08RRE-NOMFHC-EP02	
NPN, 常時開 (NO)	注文コード	BCS0131	BCS012K	
	銘板	BCS R08RRE-NSMFHC-EP00,3-GS75	BCS R08RRE-NSMFHC-EP02	
インタフェース				IO-Link
動作電圧		12.0...30.0 V	12.0...30.0 V	18.0...30.0 V
周囲温度		-25 °C...70 °C	-25 °C...70 °C	-25 °C...70 °C
ハウジング材料		PP	PP	PP
定格動作電流 Ie		50	50	50
作用面材料		PP	PP	PP
接続		コネクタ付きのケーブル, PUR, 0.30 m	ケーブル, PUR, 2.00 m	コネクタ付きのケーブル, PUR, 0.30 m M12x1-S04

www.balluff.com にさらに製品があります。



Services



You can rely on our support over the entire life cycle of our products and solutions: Including the design and planning of your projects, testing and setup on site, and training and support. For more information, visit us online at www.balluff.com/services